


# PACopaQ™

## HVAC PACKAGED SYSTEMS

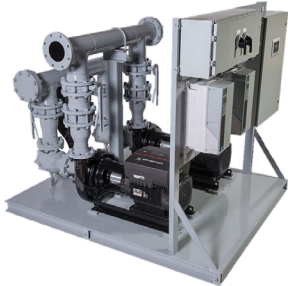

### END SUCTION SELECTION OPTIONS

4"-14" (0-4600 GPM)

Header Size	Individual Pump Flow	Pump Model	Branch Size	No. of Pumps	TDH	460 V FLA	Overall Dimensions (LCS & LC Pumps)	Approx. Weight (lbs)	Overall Dimensions (LF Pumps)	Approx. Weight (lbs)
4" 0-500 GPM	100	15955 4P 5HP	2.5"	2	75	26.5	84"Lx72"Wx72"H	2,698	102"Lx72"Wx72"H	3,180
	100	15959 4P 7.5HP	2.5"	2	100	33.7	84"Lx72"Wx72"H	2,725	102"Lx72"Wx72"H	3,109
	200	25957 4P 7.5HP	3"	2	75	33.7	84"Lx72"Wx72"H	2,725	102"Lx72"Wx72"H	3,209
	200	25957 4P 10HP	3"	2	95	40.1	84"Lx72"Wx72"H	2,751	102"Lx72"Wx72"H	3,235
	200	25123 4P 15HP	3"	2	130	55.2	84"Lx72"Wx72"H	2,917	102"Lx72"Wx72"H	3,401
	400	30957 4P 10HP	4"	2	67	40.1	84"Lx72"Wx72"H	2,751	102"Lx72"Wx72"H	3,235
	400	30127 4P 15HP	4"	2	95	55.2	84"Lx72"Wx72"H	2,917	102"Lx72"Wx72"H	3,401
	400	30127 4P 20HP	4"	2	120	68.1	84"Lx72"Wx72"H	2,945	102"Lx72"Wx72"H	3,429
6" 500-1100 GPM	450	25957 4P 7.5HP	4"	2	65	33.7	96"Lx90"Wx78"H	3,359	108"Lx90"Wx78"H	3,934
	450	25957 4P 10HP	4"	2	90	40.1	96"Lx90"Wx78"H	3,387	108"Lx90"Wx78"H	3,962
	450	30957 4P 10HP	5"	2	65	40.1	96"Lx90"Wx78"H	3,387	108"Lx90"Wx78"H	3,962
	450	30127 4P 15HP	5"	2	90	55.2	96"Lx90"Wx78"H	3,553	108"Lx90"Wx78"H	4,128
	450	30127 4P 20HP	5"	2	115	68.1	96"Lx90"Wx78"H	3,581	108"Lx90"Wx78"H	4,156
	450	30127 4P 25HP	5"	2	130	83.1	96"Lx90"Wx78"H	3,785	108"Lx90"Wx78"H	4,360
	450	30127 4P 30HP	5"	2	150	83.1	96"Lx90"Wx78"H	3,811	108"Lx90"Wx78"H	4,386
	450	30957 4P 10HP	5"	3	65	54.1	96"Lx126"Wx78"H	4,733	108"Lx126"Wx78"H	5,272
	450	30127 4P 15HP	5"	3	90	76.2	96"Lx126"Wx78"H	4,560	108"Lx126"Wx78"H	5,521
	900	50957 4P 25HP	6"	2	80	83.1	96"Lx90"Wx78"H	3,785	108"Lx90"Wx78"H	4,360
	900	4012A 4P 30 HP	6"	2	100	96.0	96"Lx90"Wx78"H	3,581	108"Lx90"Wx78"H	4,386
	450	30127 4P 20HP	5"	3	115	95.1	96"Lx126"Wx78"H	5,024	108"Lx126"Wx78"H	5,563
	450	30127 4P 25HP	5"	3	130	117.1	96"Lx126"Wx78"H	5,330	108"Lx126"Wx78"H	5,869
	900	40129 4P 40 HP	6"	2	125	121.8	96"Lx90"Wx78"H	3,925	108"Lx90"Wx78"H	5,682
	450	30127 4P 30HP	5"	3	150	136.0	96"Lx126"Wx78"H	5,369	108"Lx126"Wx78"H	5,908
	900	40129 4P 50 HP	6"	2	145	149.8	96"Lx90"Wx78"H	4,069	108"Lx90"Wx78"H	5,826
8" 900-2000 GPM	625	40957 4P 15HP	6"	2	73	55.2	96"Lx90"Wx78"H	4,252	108"Lx90"Wx78"H	4,657
	625	4012A 4P 20HP	6"	2	95	68.1	96"Lx90"Wx78"H	4,280	108"Lx90"Wx78"H	5,385
	416	30957 4P 10HP	5"	3	67	54.1	96"Lx126"Wx78"H	5,759	108"Lx126"Wx78"H	6,366
	625	4012A 4P 30HP	5"	2	125	96.0	96"Lx90"Wx78"H	4,510	108"Lx90"Wx78"H	5,615
	800	4012A 4P 30 HP	6"	2	100	96.0	96"Lx90"Wx78"H	4,510	108"Lx90"Wx78"H	4,915
	416	30127 4P 15HP	5"	3	94	76.2	96"Lx126"Wx78"H	6,008	108"Lx126"Wx78"H	6,615
	416	30127 4P 20HP	5"	3	118	95.1	96"Lx126"Wx78"H	6,050	108"Lx126"Wx78"H	6,657
	800	40129 4P 40 HP	6"	2	125	121.8	96"Lx90"Wx78"H	4,624	108"Lx90"Wx78"H	5,029
	800	50957 4P 25HP	6"	2	80	83.1	96"Lx90"Wx78"H	4,484	108"Lx90"Wx78"H	4,889
	416	30127 4P 25HP	5"	3	134	117.1	96"Lx126"Wx78"H	6,356	108"Lx126"Wx78"H	6,963
	800	40129 4P 50 HP	6"	2	145	149.8	96"Lx90"Wx78"H	4,768	108"Lx90"Wx78"H	5,173
	416	30127 4P 30HP	5"	3	150	136.0	96"Lx126"Wx78"H	6,395	108"Lx126"Wx78"H	7,002
	625	40957 4P 15HP	6"	3	73	76.2	96"Lx126"Wx78"H	6,008	108"Lx126"Wx78"H	6,615
	534	40957 4P 15HP	5"	3	73	76.2	96"Lx126"Wx78"H	6,008	108"Lx126"Wx78"H	6,615
	625	4012A 4P 20HP	6"	3	95	95.1	96"Lx126"Wx78"H	6,356	108"Lx126"Wx78"H	6,657
	800	50957 4P 25HP	6"	3	80	117.1	96"Lx126"Wx78"H	6,395	108"Lx126"Wx78"H	7,002
	625	4012A 4P 30HP	6"	3	125	136.0	96"Lx126"Wx78"H	6,395	108"Lx126"Wx78"H	7,002
	800	4012A 4P 30 HP	6"	3	100	136.0	96"Lx126"Wx78"H	6,395	108"Lx126"Wx78"H	7,002
	534	4012A 4P 30HP	5"	3	125	136.0	96"Lx126"Wx78"H	6,395	108"Lx126"Wx78"H	7,002
	800	40129 4P 40 HP	6"	3	125	173.8	96"Lx126"Wx78"H	6,566	108"Lx126"Wx78"H	7,173
800	40129 4P 50 HP	6"	3	145	214.8	96"Lx126"Wx78"H	6,782	108"Lx126"Wx78"H	7,389	

be  
think  
innovate



PACO  
LCS, LF, LC & VLS  
PUMPS




Grundfos CUE VFDs




Grundfos HVAC  
Controls



Hydronic System  
Specialties

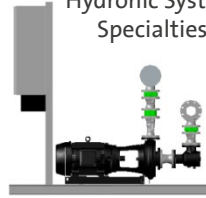

Common Structural  
Base

 

Header Size	Individual Pump Flow	Pump Model	Branch Size	No. of Pumps	TDH	460 V FLA	Overall Dimensions (LCS & LC Pumps)	Approx. Weight (lbs)	Overall Dimensions (LF Pumps)	Approx. Weight (lbs)
10" 1400-3200 GPM	1025	50123 4P 30HP	8"	2	90	96.0	114"Lx096"Wx78"H	6,126	126"Lx96"Wx78"H	6,030
	1025	50123 4P 40HP	8"	2	115	121.8	114"Lx096"Wx78"H	6,240	126"Lx96"Wx78"H	6,144
	1025	50123 4P 50HP	8"	2	140	149.8	114"Lx096"Wx78"H	6,384	126"Lx96"Wx78"H	6,288
	1025	50957 4P 25HP	8"	2	70	83.1	114"Lx096"Wx78"H	6,100	126"Lx96"Wx78"H	6,004
	683	40957 4P 15HP	6"	3	65	76.2	114"Lx138"Wx78"H	9,113	126"Lx138"Wx78"H	10,829
	683	4012A 4P 20HP	6"	3	90	95.1	114"Lx138"Wx78"H	9,155	126"Lx138"Wx78"H	10,870
	683	4012A 4P 30HP	6"	3	125	136.0	114"Lx138"Wx78"H	9,500	126"Lx138"Wx78"H	11,216
	866	50123 4P 30HP	6"	3	95	136.0	114"Lx138"Wx78"H	9,500	126"Lx138"Wx78"H	11,216
	683	40957 4P 15HP	6"	4	65	97.2	114"Lx180"Wx78"H	9,324	126"Lx180"Wx78"H	10,052
	866	50957 4P 25HP	6"	3	75	117.1	114"Lx138"Wx78"H	9,461	126"Lx138"Wx78"H	11,177
	1025	50123 4P 30HP	8"	3	90	136.0	114"Lx138"Wx78"H	9,500	126"Lx138"Wx78"H	11,216
	683	4012A 4P 20HP	6"	4	90	122.1	114"Lx180"Wx78"H	9,168	126"Lx180"Wx78"H	10,108
	1300	50123 4P 40HP	8"	3	67	173.8	114"Lx138"Wx78"H	9,500	126"Lx138"Wx78"H	11,216
	1300	50123 4P 50HP	8"	3	90	214.8	114"Lx138"Wx78"H	9,671	126"Lx138"Wx78"H	11,387
	1025	50123 4P 40HP	8"	3	115	173.8	114"Lx138"Wx78"H	9,671	126"Lx138"Wx78"H	11,387
	866	50957 4P 30HP	6"	3	120	136.0	114"Lx138"Wx78"H	9,671	126"Lx138"Wx78"H	11,387
	1025	50123 4P 40HP	8"	3	140	173.8	114"Lx138"Wx78"H	9,887	126"Lx138"Wx78"H	11,603
	1025	50957 4P 25HP	8"	3	70	117.1	114"Lx138"Wx78"H	9,461	126"Lx138"Wx78"H	11,177
	866	50957 4P 25HP	6"	4	75	151.1	114"Lx180"Wx78"H	9,576	126"Lx180"Wx78"H	10,516
	866	4012A 4P 30HP	6"	4	95	176.0	114"Lx180"Wx78"H	9,628	126"Lx180"Wx78"H	10,568
683	50123 4P 30HP	6"	4	125	176.0	114"Lx180"Wx78"H	9,628	126"Lx180"Wx78"H	10,568	
866	50123 4P 50HP	6"	3	145	214.8	114"Lx138"Wx78"H	9,887	126"Lx138"Wx78"H	11,603	
866	50123 4P 40HP	6"	4	120	225.8	114"Lx180"Wx78"H	9,856	126"Lx180"Wx78"H	10,796	
1300	60123 4P 60HP	8"	3	120	252.6	120"Lx138"Wx78"H	10,015	132"Lx138"Wx78"H	10,970	
866	50123 4P 50HP	6"	4	145	279.8	114"Lx180"Wx78"H	11,084	126"Lx180"Wx78"H	14,693	
1300	60123 4P 75HP	8"	3	140	312.4	120"Lx138"Wx78"H	10,441	132"Lx138"Wx78"H	11,416	
12" 2400-3900 GPM	765	40129 4P 25HP	6"	3	85	117.1	114"Lx138"Wx78"H	8,888	126"Lx138"Wx78"H	12,398
	1000	40129 4P 40HP	8"	3	120	173.8	114"Lx138"Wx78"H	9,098	126"Lx138"Wx78"H	12,608
	1020	50957 4P 25HP	8"	3	75	117.1	114"Lx138"Wx78"H	8,888	126"Lx138"Wx78"H	12,398
	1020	50123 4P 30HP	8"	3	95	136.0	114"Lx138"Wx78"H	8,927	126"Lx138"Wx78"H	12,437
	1020	50123 4P 40HP	8"	3	115	173.8	114"Lx138"Wx78"H	9,098	126"Lx138"Wx78"H	12,608
	1020	50123 4P 50HP	8"	3	140	214.8	114"Lx138"Wx78"H	9,314	126"Lx138"Wx78"H	12,824
	1200	60123 4P 60HP	8"	3	120	252.6	120"Lx138"Wx78"H	9,767	132"Lx138"Wx78"H	10,694
	1200	60123 4P 75HP	8"	3	145	312.4	120"Lx138"Wx78"H	10,193	132"Lx138"Wx78"H	11,172
	765	40129 4P 25HP	6"	4	85	151.1	114"Lx180"Wx78"H	11,446	126"Lx180"Wx78"H	14,125
	1000	40129 4P 40HP	8"	4	120	225.8	114"Lx180"Wx78"H	11,726	126"Lx180"Wx78"H	14,405
	1020	50957 4P 25HP	8"	4	75	151.1	114"Lx180"Wx78"H	11,446	126"Lx180"Wx78"H	14,125
	1020	50123 4P 30HP	8"	4	95	176.0	114"Lx180"Wx78"H	11,498	126"Lx180"Wx78"H	14,177
	1020	50123 4P 40HP	8"	4	115	225.8	114"Lx180"Wx78"H	11,726	126"Lx180"Wx78"H	14,405
	1020	50123 4P 50HP	8"	4	140	279.8	114"Lx180"Wx78"H	12,014	126"Lx180"Wx78"H	14,693
	1200	60123 4P 60HP	8"	4	120	329.6	120"Lx180"Wx78"H	12,618	132"Lx180"Wx78"H	13,829
	1200	60123 4P 75HP	8"	4	145	408.4	120"Lx180"Wx78"H	13,186	132"Lx180"Wx78"H	14,452
14" 3000-4600 GPM	1100	50957 4P 25HP	8"	3	70	117.1	120"Lx156"Wx78"H	12,809	132"Lx156"Wx78"H	11,953
	1100	50123 4P 40HP	8"	3	115	173.8	120"Lx156"Wx78"H	13,019	132"Lx156"Wx78"H	12,163
	1100	50123 4P 50HP	8"	3	140	214.8	120"Lx156"Wx78"H	13,235	132"Lx156"Wx78"H	12,379
	1200	60123 4P 50HP	8"	3	110	214.8	120"Lx156"Wx78"H	13,235	132"Lx156"Wx78"H	12,739
	1200	60123 4P 60HP	8"	3	120	252.6	120"Lx156"Wx78"H	13,688	132"Lx156"Wx78"H	12,832
	1200	60123 4P 75HP	8"	3	140	312.4	120"Lx156"Wx78"H	14,114	132"Lx156"Wx78"H	13,258
	1100	50957 4P 25HP	8"	4	70	151.1	120"Lx204"Wx78"H	12,450	132"Lx204"Wx78"H	14,957
	1100	50123 4P 40HP	8"	4	115	225.8	120"Lx204"Wx78"H	12,733	132"Lx204"Wx78"H	15,237
	1100	50123 4P 50HP	8"	4	140	279.8	120"Lx204"Wx78"H	13,021	132"Lx204"Wx78"H	15,525
	1200	60123 4P 50HP	8"	4	110	279.8	120"Lx204"Wx78"H	13,021	132"Lx204"Wx78"H	15,525
	1200	60123 4P 60HP	8"	4	120	329.6	120"Lx204"Wx78"H	13,625	132"Lx204"Wx78"H	16,129
	1200	60123 4P 75HP	8"	4	140	408.4	120"Lx204"Wx78"H	14,193	132"Lx204"Wx78"H	13,649

GRUNDFOS  
902 Koomey Road  
Brookshire, TX 77423  
281-994-2700  
800-955-5847

[www.grundfosexpresssuite.com](http://www.grundfosexpresssuite.com)  
[www.grundfos.us](http://www.grundfos.us)

The name Grundfos, the Grundfos logo, and be think innovate are registered trademarks owned by Grundfos Holding A/S or Grundfos A/S, Denmark. All rights reserved worldwide.

